



**DeviceNet**

Drop T-piece

1/1

**Data sheet**

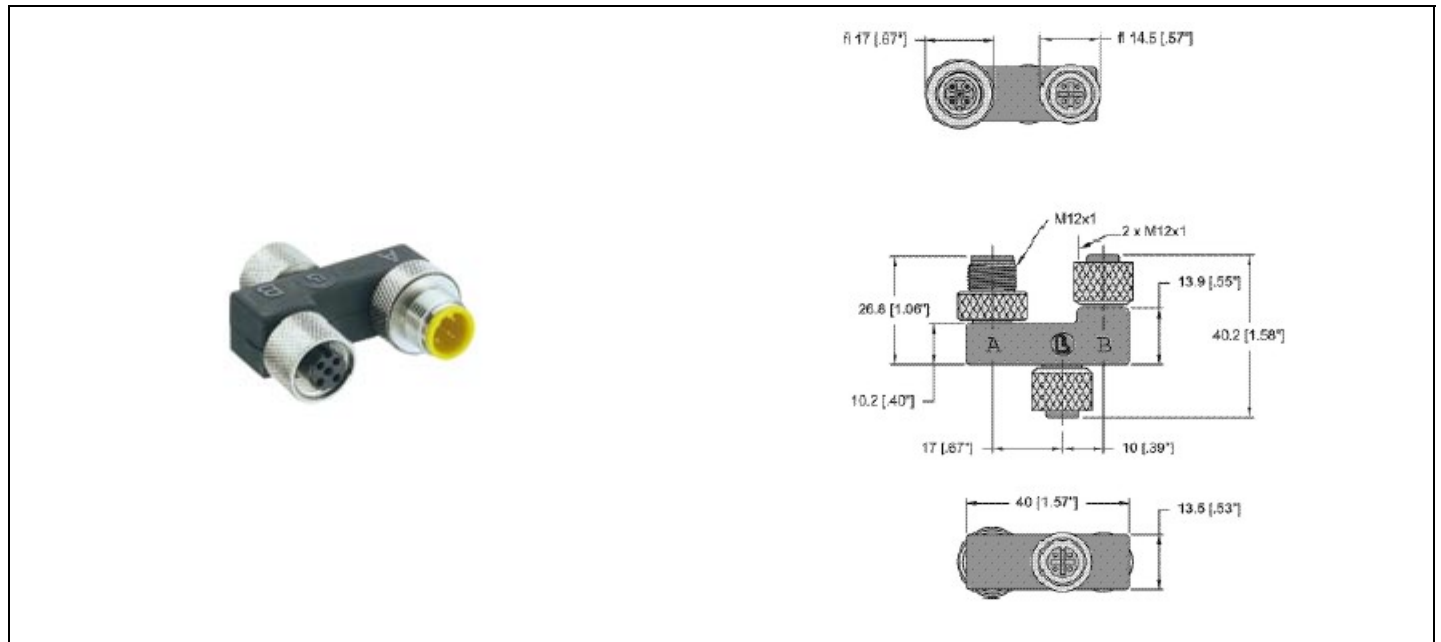

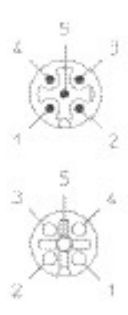Description	Item-No.	Pack.-unit pcs
M12 DeviceNet drop T-piece, 5 poles	755-808	1
<p>T connector, 5 poles, for DeviceNet modules with bus connection M12.</p> <p>Pin assignment:</p>  <ol style="list-style-type: none"> <li>1. Drain</li> <li>2. DC 24 V</li> <li>3. 0 V</li> <li>4. CAN_H</li> <li>5. CAN_L</li> </ol>	<p><b>Technical Data</b></p> <p><b>Electrical data:</b></p> <p>Nominal power 4 A</p> <p>Nominal voltage AC 30 V / DC 36 V</p> <p><b>Mechanical data:</b></p> <p>Degree of protection * IP68, Nema 6P</p> <p>Temperature range -25 °C...+90 °C</p> <p><b>Material:</b></p> <p>Moulded body TPU</p> <p>Contact CuZn, pre-nickel and gold-plated acc. to DeviceNet specification</p> <p>Locking nut CuZn, brass, nickel</p> <p>* IP68 only in fully locked position with ist plugs.</p>	