


DeviceNet

7/8" T-piece for power supply


1/1

Data sheet

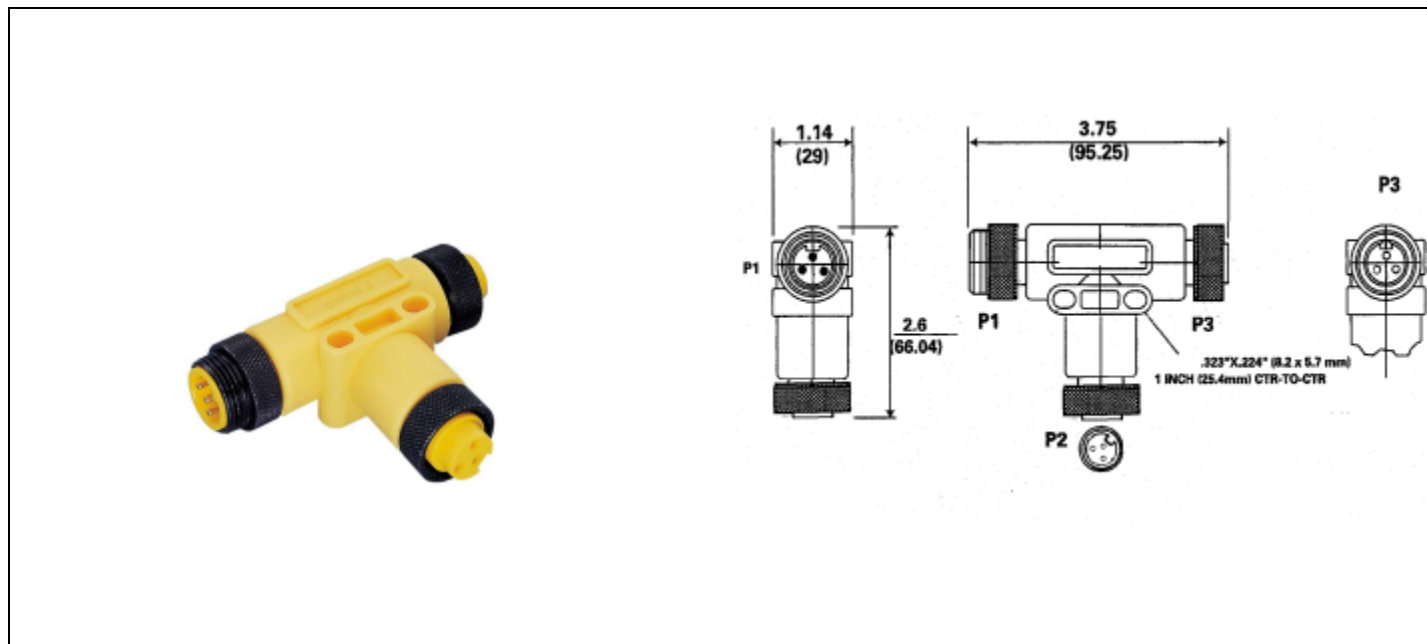

Description	Item-No.	Pack.-unit pcs
7/8" T-piece, 3 poles	755-854	1

 - Cable connection:
1. GND
 2. DC +24 V
 3. 0 V



Technical Data

Electrical Data:

Working voltage	AC 600 V
Rated current (40 °C)	10 A
Contact resistance	≤ 5 mΩ
Insulation resistance	> 10 ⁹ Ω

Mechanical data:

Degree of protection	IP 68, NEMA 6P (when fully locked)
Shock	IEC 68-2-27
Vibration	IEC 68-2-6
Operating temperature	-40 °C...+90 °C

Material:

Body	PUR, yellow
Contact	Solid-machined brass
Insert	PUR
Coupling nut	Standard: Aluminium (black anodized)

Standards / prescriptions: UL, CSA