


Multi-Port Device Taps, DeviceNet compatible

2 trunk Cable (input, output), 4 drop cables, IP 65 / NEMA 4 enclosure

Data sheet

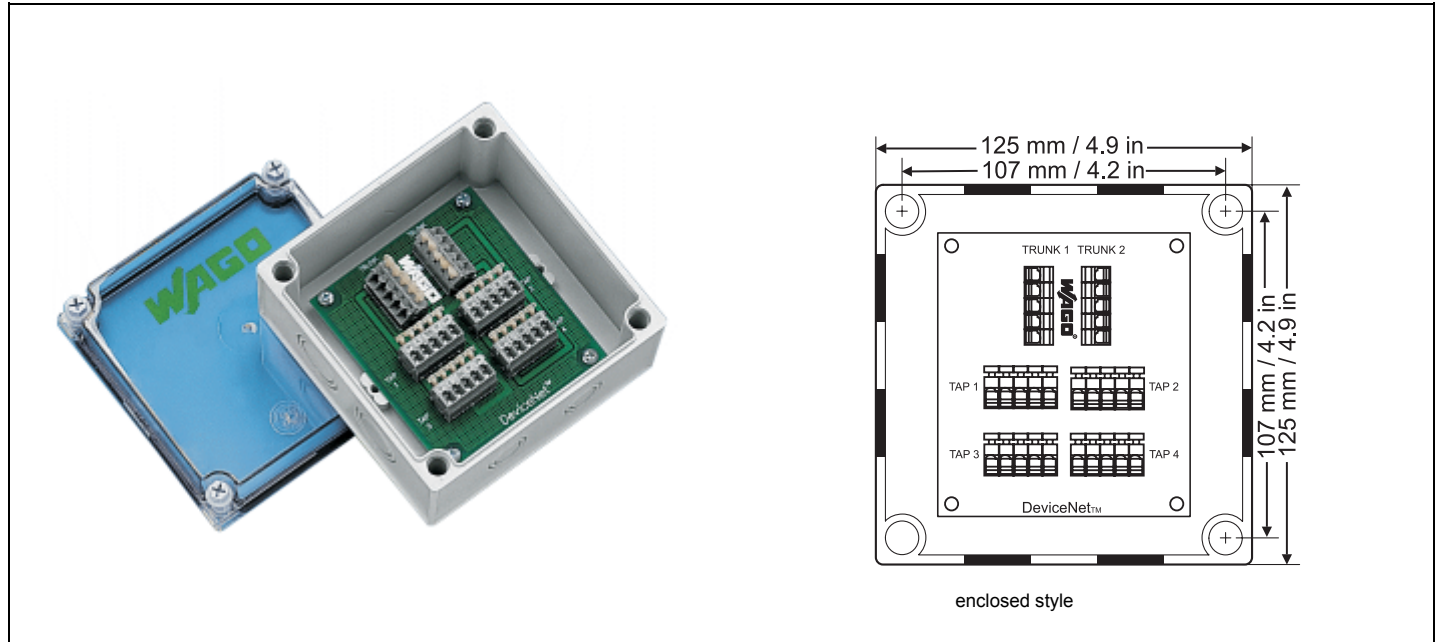

Description	Item-No.	Pack.-unit pcs																
Multi-port device tap 2 trunk cables (input, output); 4 drop cables IP 65 / NEMA 4 enclosure	810-900/000-001	1																
<ul style="list-style-type: none"> This multi-port device taps allow the connection of up to 4 drop cables. The electrical connections are made using PCB terminal strips with lever, so that the junction boxes can be installed in places with difficult access. Cable grips shown are sold separately (see accessories below) DeviceNet requires a terminating resistor to be installed at each end of the trunk. The resistor (metal film resistor) requirements are: 121 Ω ± 1 %, ¼ Watt. Termination resistors should not be installed at the end of a drop; only at the two ends of the main trunk, as required. 	<h3>Technical Data</h3> <table border="1"> <tr> <td>CAGE CLAMP® connections</td> <td>PCB terminal strips</td> </tr> <tr> <td>For trunk cable</td> <td>2 x 256-405</td> </tr> <tr> <td>For drop cable</td> <td>4 x 255-405</td> </tr> <tr> <td>Enclosure</td> <td>with knockouts for cable grips</td> </tr> <tr> <td>Wire range</td> <td>0,08–2,5 mm² / AWG 28-12</td> </tr> <tr> <td>Trunk cable</td> <td>Ø 10-14 mm</td> </tr> <tr> <td>Drop cable</td> <td>Ø 06-12 mm</td> </tr> <tr> <td>Degree of protection (enclosure)</td> <td>IP 65 / NEMA 4</td> </tr> </table>		CAGE CLAMP® connections	PCB terminal strips	For trunk cable	2 x 256-405	For drop cable	4 x 255-405	Enclosure	with knockouts for cable grips	Wire range	0,08–2,5 mm ² / AWG 28-12	Trunk cable	Ø 10-14 mm	Drop cable	Ø 06-12 mm	Degree of protection (enclosure)	IP 65 / NEMA 4
CAGE CLAMP® connections	PCB terminal strips																	
For trunk cable	2 x 256-405																	
For drop cable	4 x 255-405																	
Enclosure	with knockouts for cable grips																	
Wire range	0,08–2,5 mm ² / AWG 28-12																	
Trunk cable	Ø 10-14 mm																	
Drop cable	Ø 06-12 mm																	
Degree of protection (enclosure)	IP 65 / NEMA 4																	
<h3>Application Notes</h3>	<h3>Accessories</h3> <table border="1"> <tr> <td>Test adapter for mini banana plug</td> <td>810-900/004-000</td> </tr> <tr> <td>Grips for</td> <td></td> </tr> <tr> <td>- trunk cable Ø 10-14 mm</td> <td>810-900/001-000</td> </tr> <tr> <td>- drop cable Ø 06-12 mm</td> <td>810-900/002-000</td> </tr> <tr> <td>Termination resistor</td> <td>810-900/003-000</td> </tr> </table>		Test adapter for mini banana plug	810-900/004-000	Grips for		- trunk cable Ø 10-14 mm	810-900/001-000	- drop cable Ø 06-12 mm	810-900/002-000	Termination resistor	810-900/003-000						
Test adapter for mini banana plug	810-900/004-000																	
Grips for																		
- trunk cable Ø 10-14 mm	810-900/001-000																	
- drop cable Ø 06-12 mm	810-900/002-000																	
Termination resistor	810-900/003-000																	