


Sockets for miniature switching relay and SSR

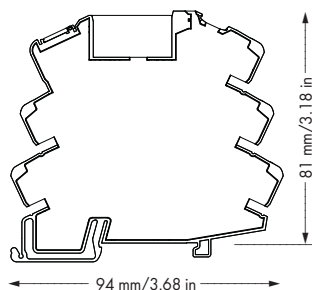

Description	Item No.	Pack. Unit	
Socket for miniature switching relay and SSR, 24 V AC/DC for DIN 35 rail	857-104	1	
Socket for miniature switching relay and SSR, 110 V AC/DC for DIN 35 rail	857-107	1	
Socket for miniature switching relay and SSR, 230 V AC/DC for DIN 35 rail	857-108	1	

Technical Data

Status indication	LED yellow	
Operating temperature	-25 °C ... +70 °C	
Storage temperature	-40 °C ... +70 °C	
Dimensions (mm) W x H x L	6 x 81 x 94	
Wire connection	Height from upper edge of DIN 35 rail CAGE CLAMP® S	
Cross sections	0.34 mm² ... 2.5 mm² / AWG 22 ... 12	
Strip length	9 ... 10 mm / 0.37 in	
Approvals		

Assignment Socket / Replacement Relay / Replacement Optocoupler

	Input Voltage	Item No.	Socket	Replacement Relays or Optocouplers
Miniature Switching Relays	12 V DC	857-303	857-103	857-150
	24 V DC	857-304	857-104	857-152
	48 V DC	857-305	857-105	857-154
	60 V DC	857-306	857-106	857-155
	110 V DC	857-307	857-107	857-155
	220 V DC	857-308	857-108	857-155
	24 V AC/DC	857-354	857-104	857-152
	115 V AC/DC	857-357	857-107	857-155
	230 V AC/DC	857-358	857-108	857-155
Miniature Switching Relays (gold contacts)	24 V DC	857-314	857-104	857-153
	110 V DC	857-317	857-107	857-157
	220 V DC	857-318	857-108	857-157
	24 V AC/DC	857-364	857-104	857-153
	115 V AC/DC	857-367	857-107	857-157
	230 V AC/DC	857-368	857-108	857-157
	24 V DC	857-704	857-104	857-164
Solid State Relays	115 V AC/DC	857-707	857-107	857-165
	230 V AC/DC	857-708	857-108	857-165
	24 V DC	857-714	857-104	857-167
	115 V AC/DC	857-717	857-107	857-168
	230 V AC/DC	857-718	857-108	857-168
	24 V DC	857-724	857-104	857-161
	115 V AC/DC	857-727	857-107	857-162
	230 V AC/DC	857-728	857-108	857-162