


## Edge Computer; 2 x ETHERNET, 4 x USB, HDMI, DP; 4 or 8 GB RAM, 64 GB Flash

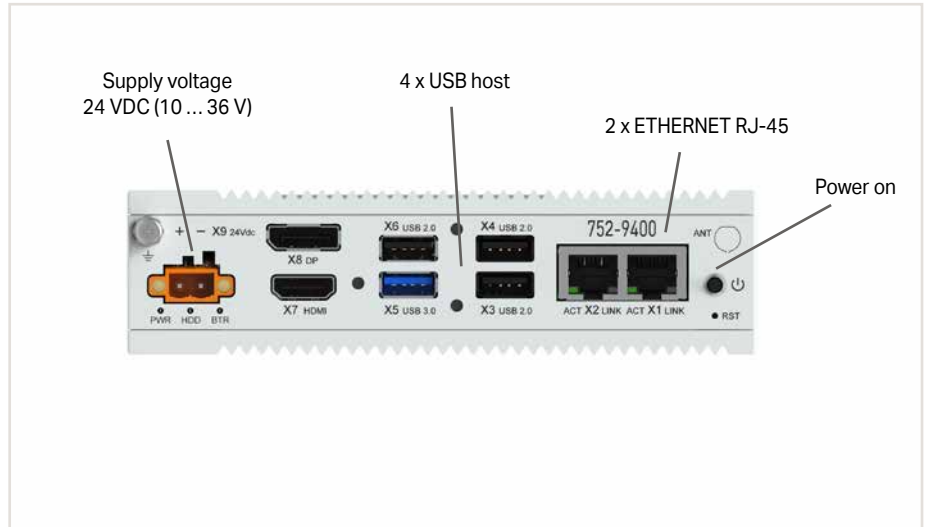

- 2 x ETHERNET interface for connecting to field devices and IT networks
- 4 x USB interface for optional connection of a USB stick, mouse or keyboard
- HDMI and display port interfaces for connecting a display

Item Description	Edge Computer; 2 x ETHERNET, 4 x USB, HDMI, DP	
Version	4 GB RAM, 64 GB Flash	8 GB RAM, 64 GB Flash
Item No.	752-9400	752-9401
Order Text	EC; 2ETH, 4USB, HDMI, DP; 4GB RAM, 64GB Flash	EC; 2ETH, 4USB, HDMI, DP; 8GB RAM, 64GB Flash

Technical Data		
Communication	Web Browser	
Visualization	Web server	
ETHERNET protocols	DHCP; DNS; HTTP; HTTPS; SSH; SCP; SFTP	
Operating system	Debian Linux 10.9	
Processor	Intel® Atom Quadcore E3845 1.91 GHz	
Main memory (RAM)	4 GB; DDR3L 1333 MHz	8 GB; DDR3L 1333 MHz
Internal memory (flash)	64 GB; mSATA SSD	
Memory expansion	Full-size mPCIe slot; Drive mount for a 2.5" SSD HDD memory card (height: 9.5 mm)	
RTC (Real-Time Clock)	Battery type BR2032; 3 VDC	
Indicators	3 x LED	
Connection technology: communication/fieldbus	ETHERNET: 2 x RJ-45 socket	
Transmission rate	ETHERNET: 10/100/1000 Mbit/s	
Interfaces	1 x USB 3.0 socket, Type A; 3 x USB 2.0 socket, Type A; 1 x HDMI v1.4, 1920 x 1080p @60Hz; 1 x DisplayPort 1.2, 2560 x 440p	
Supply voltage	24 VDC (10 ... 36 V)	
Input current (24 V)	1250 mA (typ.); 1750 mA (max.)	
Operating power	30 W (typ.); 42 W (max.)	
Dimensions (W x H x D)	40 x 150 x 105 mm	
Housing material	Aluminum, powder-coated	
Weight	809 g	
Surrounding air temperature (operation)	-20 ... +60 °C	
Surrounding air temperature (storage)	-40 ... +85 °C	
Protection type	IP40	
Relative humidity (without condensation)	95 %	
Mounting type	DIN-35-rail mount	
Approvals	E482462 Ordinary Locations, UL62368	