




PROFIBUS cable

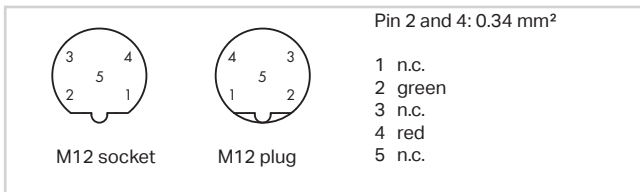


Connection technology	M12 socket/plug, B coded
Operating voltage	≤ 300 V
Operating current	4 A
Rated surge voltage	≥ 2 kV
Suitable for drag chain applications	≥ 1 Mio. bending cycles
Ambient temperature (operation) moved	-25 ... +60 °C
Protection type	IP67
Cable diameter	7.6 mm ±0.3

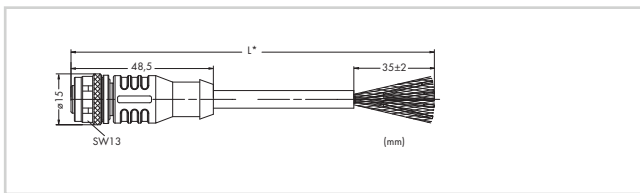


PROFIBUS cable, M12 socket, straight, B coded		
	Item No.	Pack. Unit
M12 socket, straight, 2 m	756-1101/060-020	1
M12 socket, straight, 5 m	756-1101/060-050	1
M12 socket, straight, 10 m	756-1101/060-100	1
M12 socket, straight, 20 m	756-1101/060-200	1

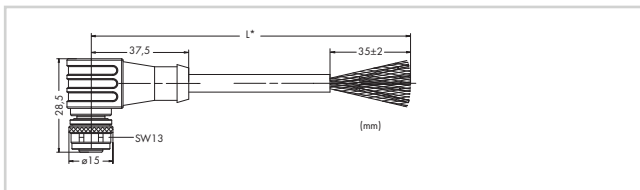

PROFIBUS cable, M12 socket, right angle, B coded		
	Item No.	Pack. Unit
M12 socket, right angle, 2 m	756-1102/060-020	1
M12 socket, right angle, 5 m	756-1102/060-050	1
M12 socket, right angle, 10 m	756-1102/060-100	1
M12 socket, right angle, 20 m	756-1102/060-200	1


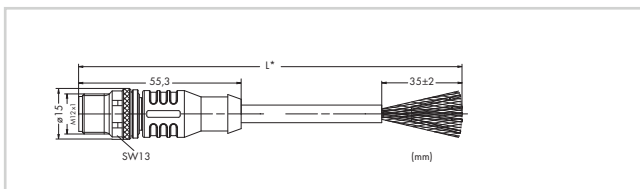


PROFIBUS cable, M12 plug, straight, B coded		
	Item No.	Pack. Unit
M12 plug, straight, 2 m	756-1103/060-020	1
M12 plug, straight, 5 m	756-1103/060-050	1
M12 plug, straight, 10 m	756-1103/060-100	1
M12 plug, straight, 20 m	756-1103/060-200	1

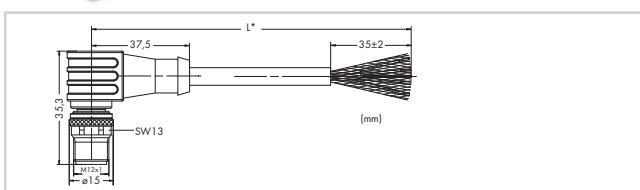

PROFIBUS cable, M12 plug, right angle, B coded		
	Item No.	Pack. Unit
M12 plug, right angle, 2 m	756-1104/060-020	1
M12 plug, right angle, 5 m	756-1104/060-050	1
M12 plug, right angle, 10 m	756-1104/060-100	1
M12 plug, right angle, 20 m	756-1104/060-200	1

PROFIBUS cable

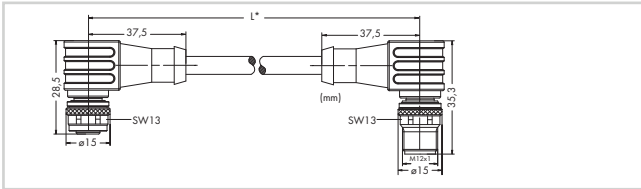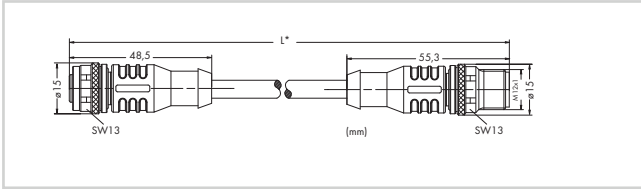

PROFIBUS cable, M12 socket – M12 plug, straight, B coded

	Item No.	Pack. Unit
M12 socket, straight, M12 plug, straight, 2 m	756-1105/060-020	1
M12 socket, straight, M12 plug, straight, 5 m	756-1105/060-050	1
M12 socket, straight, M12 plug, straight, 10 m	756-1105/060-100	1
M12 socket, straight, M12 plug, straight, 20 m	756-1105/060-200	1

PROFIBUS cable, M12 socket – M12 plug, right angle, B coded

	Item No.	Pack. Unit
M12 socket, right angle, M12 plug, right angle, 2 m	756-1106/060-020	1
M12 socket, right angle, M12 plug, right angle, 5 m	756-1106/060-050	1
M12 socket, right angle, M12 plug, right angle, 10 m	756-1106/060-100	1
M12 socket, right angle, M12 plug, right angle, 20 m	756-1106/060-200	1