




ETHERNET/PROFINET cable

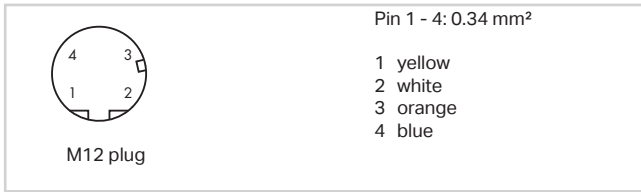


Connection technology	M12 plug, D coded
Operating voltage	250 V
Operating current	4 A
Rated surge voltage	2 kV
Suitable for drag chain applications	≥ 3 Mio. bending cycles
Ambient temperature (operation) moved	-40 ... +70 °C
Protection type	IP67
Cable diameter	6.5 mm ±0.2

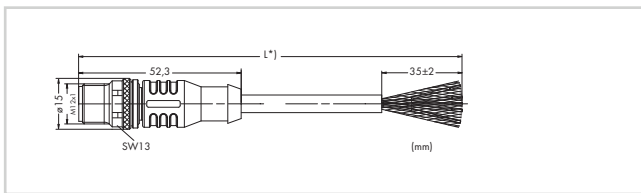


ETHERNET/PROFINET cable, M12 plug, straight, D coded		
	Item No.	Pack. Unit
M12 plug, straight, 2 m	756-1201/060-020	1
M12 plug, straight, 5 m	756-1201/060-050	1
M12 plug, straight, 10 m	756-1201/060-100	1
M12 plug, straight, 20 m	756-1201/060-200	1

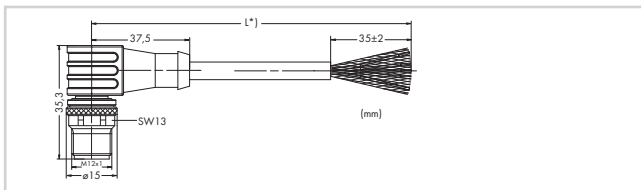

ETHERNET/PROFINET cable, M12 plug, right angle, D coded		
	Item No.	Pack. Unit
M12 plug, right angle, 2 m	756-1202/060-020	1
M12 plug, right angle, 5 m	756-1202/060-050	1
M12 plug, right angle, 10 m	756-1202/060-100	1
M12 plug, right angle, 20 m	756-1202/060-200	1

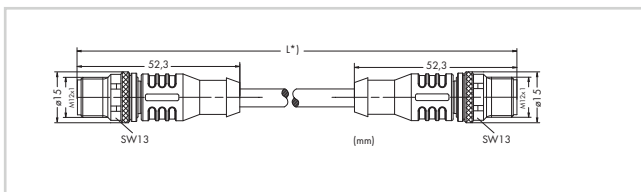

ETHERNET/PROFINET cable, M12 plug – M12 plug, straight, D coded		
	Item No.	Pack. Unit
M12 plug, straight, M12 plug, straight, 2 m	756-1203/060-020	1
M12 plug, straight, M12 plug, straight, 5 m	756-1203/060-050	1
M12 plug, straight, M12 plug, straight, 10 m	756-1203/060-100	1
M12 plug, straight, M12 plug, straight, 20 m	756-1203/060-200	1

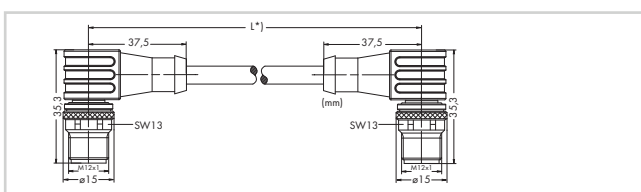

ETHERNET/PROFINET cable, M12 plug – M12 plug, right angle, D coded		
	Item No.	Pack. Unit
M12 plug, right angle, M12 plug, right angle, 2 m	756-1204/060-020	1
M12 plug, right angle, M12 plug, right angle, 5 m	756-1204/060-050	1
M12 plug, right angle, M12 plug, right angle, 10 m	756-1204/060-100	1
M12 plug, right angle, M12 plug, right angle, 20 m	756-1204/060-200	1