




System bus cable

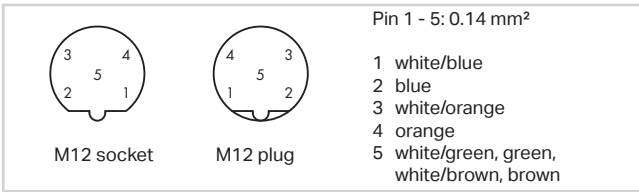


Connection technology	M12 socket/plug, B coded
Operating voltage	≤ 60 V
Operating current	4 A
Rated surge voltage	1.5 kV
Ambient temperature (operation)	-25 ... +60 °C
Protection type	IP67
Cable diameter	6 mm

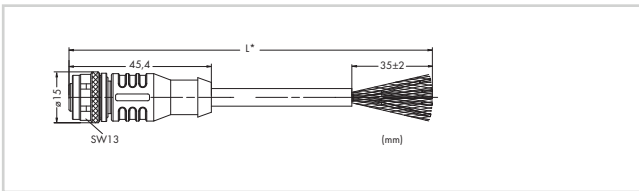


System bus cable, M12 socket, straight, B coded		
	Item No.	Pack. Unit
M12 socket, straight, 2 m	756-1301/060-020	1
M12 socket, straight, 5 m	756-1301/060-050	1
M12 socket, straight, 10 m	756-1301/060-100	1
M12 socket, straight, 20 m	756-1301/060-200	1

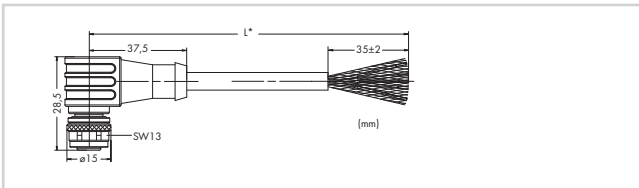

System bus cable, M12 socket, right angle, B coded		
	Item No.	Pack. Unit
M12 socket, right angle, 2 m	756-1302/060-020	1
M12 socket, right angle, 5 m	756-1302/060-050	1
M12 socket, right angle, 10 m	756-1302/060-100	1
M12 socket, right angle, 20 m	756-1302/060-200	1



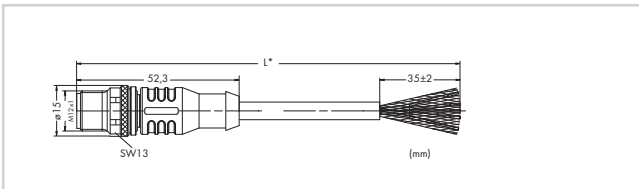


System bus cable, M12 plug, straight, B coded		
	Item No.	Pack. Unit
M12 plug, straight, 2 m	756-1303/060-020	1
M12 plug, straight, 5 m	756-1303/060-050	1
M12 plug, straight, 10 m	756-1303/060-100	1
M12 plug, straight, 20 m	756-1303/060-200	1

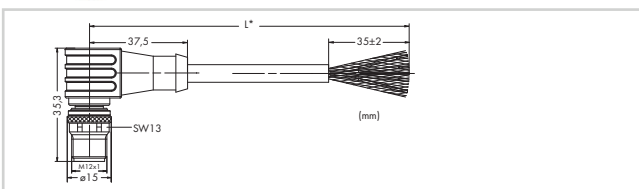

System bus cable, M12 plug, right angle, B coded		
	Item No.	Pack. Unit
M12 plug, right angle, 2 m	756-1304/060-020	1
M12 plug, right angle, 5 m	756-1304/060-050	1
M12 plug, right angle, 10 m	756-1304/060-100	1
M12 plug, right angle, 20 m	756-1304/060-200	1

System bus cable

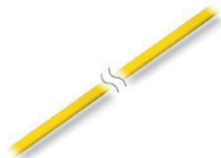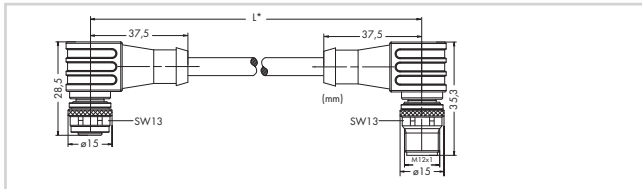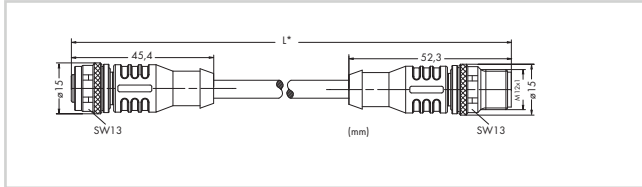

System bus cable, M12 socket – M12 plug, straight, B coded

	Item No.	Pack. Unit
M12 socket, straight, M12 plug, straight, 0.2 m	756-1305/060-002	1
M12 socket, straight, M12 plug, straight, 0.3 m	756-1305/060-003	1
M12 socket, straight, M12 plug, straight, 0.5 m	756-1305/060-005	1
M12 socket, straight, M12 plug, straight, 1 m	756-1305/060-010	1
M12 socket, straight, M12 plug, straight, 2 m	756-1305/060-020	1
M12 socket, straight, M12 plug, straight, 3 m	756-1305/060-030	1
M12 socket, straight, M12 plug, straight, 5 m	756-1305/060-050	1
M12 socket, straight, M12 plug, straight, 7 m	756-1305/060-070	1
M12 socket, straight, M12 plug, straight, 10 m	756-1305/060-100	1
M12 socket, straight, M12 plug, straight, 20 m	756-1305/060-200	1
M12 socket, straight, M12 plug, straight, 50 m	756-1305/060-500	1

System bus cable, M12 socket – M12 plug, right angle, B coded

	Item No.	Pack. Unit
M12 socket, right angle, M12 plug, right angle, 0.2 m	756-1306/060-002	1
M12 socket, right angle, M12 plug, right angle, 0.3 m	756-1306/060-003	1
M12 socket, right angle, M12 plug, right angle, 0.5 m	756-1306/060-005	1
M12 socket, right angle, M12 plug, right angle, 1 m	756-1306/060-010	1
M12 socket, right angle, M12 plug, right angle, 2 m	756-1306/060-020	1
M12 socket, right angle, M12 plug, right angle, 3 m	756-1306/060-030	1
M12 socket, right angle, M12 plug, right angle, 5 m	756-1306/060-050	1
M12 socket, right angle, M12 plug, right angle, 7 m	756-1306/060-070	1
M12 socket, right angle, M12 plug, right angle, 10 m	756-1306/060-100	1
M12 socket, right angle, M12 plug, right angle, 20 m	756-1306/060-200	1
M12 socket, right angle, M12 plug, right angle, 50 m	756-1306/060-500	1

System bus cable

	Item No.	Pack. Unit
25 m	756-1300/000-250	1
50 m	756-1300/000-500	1
100 m	756-1300/000-1000	1