




# CANopen/DeviceNet cable

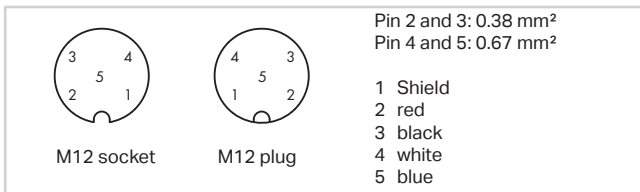


Connection technology	M12 socket/ plug, A coded
Operating voltage	≤ 300 V
Operating current	4 A
Rated surge voltage	2 kV
Suitable for drag chain applications	≥ 5 Mio. bending cycles
Ambient temperature (operation) moved	-40 ... +80 °C
Protection type	IP67
Cable diameter	6.9 mm ±0.3

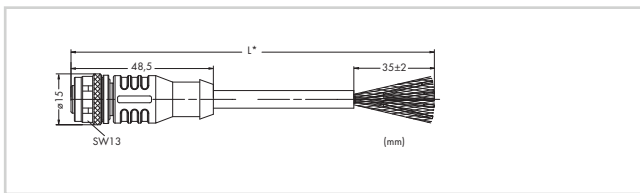


CANopen/DeviceNet cable, M12 socket, straight, A coded		
	Item No.	Pack. Unit
M12 socket, straight, 2 m	756-1401/060-020	1
M12 socket, straight, 5 m	756-1401/060-050	1
M12 socket, straight, 10 m	756-1401/060-100	1
M12 socket, straight, 20 m	756-1401/060-200	1

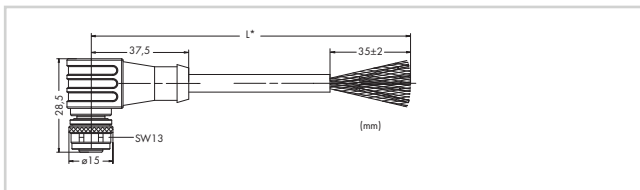

CANopen/DeviceNet cable, M12 socket, right angle, A coded		
	Item No.	Pack. Unit
M12 socket, right angle, 2 m	756-1402/060-020	1
M12 socket, right angle, 5 m	756-1402/060-050	1
M12 socket, right angle, 10 m	756-1402/060-100	1
M12 socket, right angle, 20 m	756-1402/060-200	1


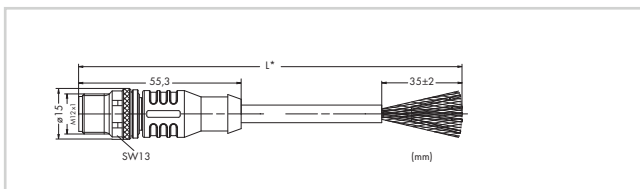


CANopen/DeviceNet cable, M12 plug, straight, A coded		
	Item No.	Pack. Unit
M12 plug, straight, 2 m	756-1403/060-020	1
M12 plug, straight, 5 m	756-1403/060-050	1
M12 plug, straight, 10 m	756-1403/060-100	1
M12 plug, straight, 20 m	756-1403/060-200	1

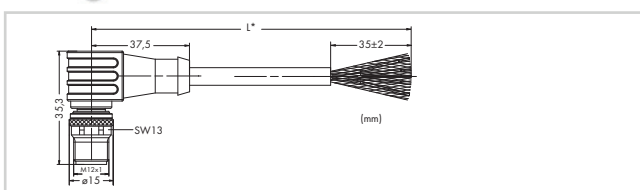

CANopen/DeviceNet cable, M12 plug, right angle, A coded		
	Item No.	Pack. Unit
M12 plug, right angle, 2 m	756-1404/060-020	1
M12 plug, right angle, 5 m	756-1404/060-050	1
M12 plug, right angle, 10 m	756-1404/060-100	1
M12 plug, right angle, 20 m	756-1404/060-200	1

# CANopen/DeviceNet cable

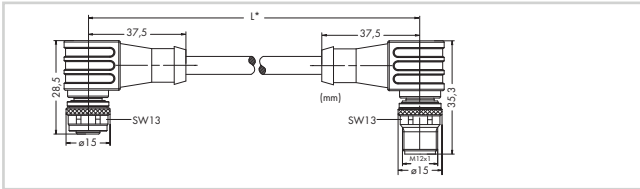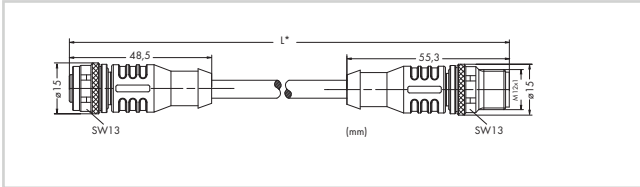

## CANopen/DeviceNet cable, M12 socket – M12 plug, straight, A coded

	Item No.	Pack. Unit
M12 socket, straight, M12 plug, straight, 2 m	756-1405/060-020	1
M12 socket, straight, M12 plug, straight, 5 m	756-1405/060-050	1
M12 socket, straight, M12 plug, straight, 10 m	756-1405/060-100	1
M12 socket, straight, M12 plug, straight, 20 m	756-1405/060-200	1

## CANopen/DeviceNet cable, M12 socket – M12 plug, right angle, A coded

	Item No.	Pack. Unit
M12 socket, right angle, M12 plug, right angle, 2 m	756-1406/060-020	1
M12 socket, right angle, M12 plug, right angle, 5 m	756-1406/060-050	1
M12 socket, right angle, M12 plug, right angle, 10 m	756-1406/060-100	1
M12 socket, right angle, M12 plug, right angle, 20 m	756-1406/060-200	1