




# System bus cable for drag chain

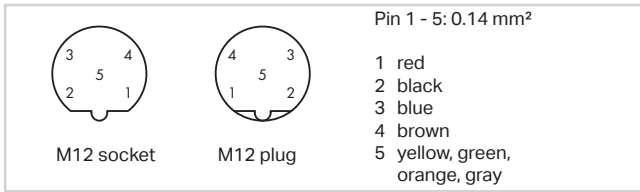


Connection technology	M12 socket/plug, B coded
Operating voltage	≤ 60 V
Operating current	4 A
Rated surge voltage	1.5 kV
Suitable for drag chain applications	≥ 5 Mio. bending cycles
Ambient temperature (operation) moved	0 ... +50 °C
Protection type	IP67
Cable diameter	6.8 mm

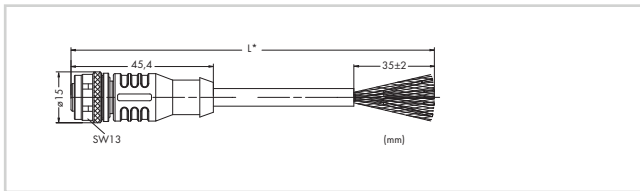


System bus cable for drag chain, M12 socket, straight, B coded		
	Item No.	Pack. Unit
M12 socket, straight, 2 m	756-1501/060-020	1
M12 socket, straight, 5 m	756-1501/060-050	1
M12 socket, straight, 10 m	756-1501/060-100	1
M12 socket, straight, 20 m	756-1501/060-200	1

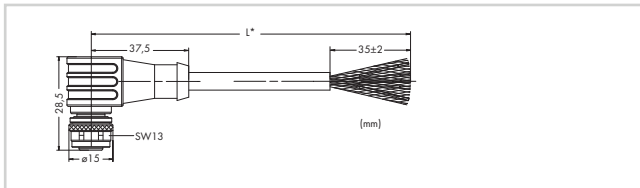

System bus cable for drag chain, M12 socket, right angle, B coded		
	Item No.	Pack. Unit
M12 socket, right angle, 2 m	756-1502/060-020	1
M12 socket, right angle, 5 m	756-1502/060-050	1
M12 socket, right angle, 10 m	756-1502/060-100	1
M12 socket, right angle, 20 m	756-1502/060-200	1


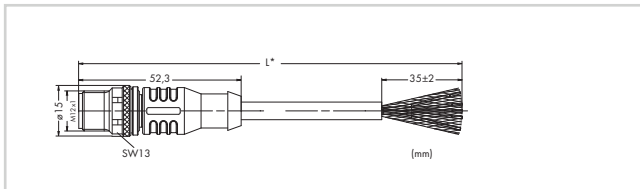


System bus cable for drag chain, M12 plug, straight, B coded		
	Item No.	Pack. Unit
M12 plug, straight, 2 m	756-1503/060-020	1
M12 plug, straight, 5 m	756-1503/060-050	1
M12 plug, straight, 10 m	756-1503/060-100	1
M12 plug, straight, 20 m	756-1503/060-200	1

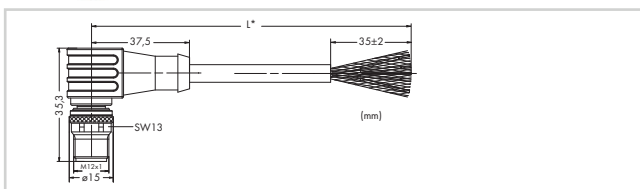

System bus cable for drag chain, M12 plug, right angle, B coded		
	Item No.	Pack. Unit
M12 plug, right angle, 2 m	756-1504/060-020	1
M12 plug, right angle, 5 m	756-1504/060-050	1
M12 plug, right angle, 10 m	756-1504/060-100	1
M12 plug, right angle, 20 m	756-1504/060-200	1

## System bus cable for drag chain

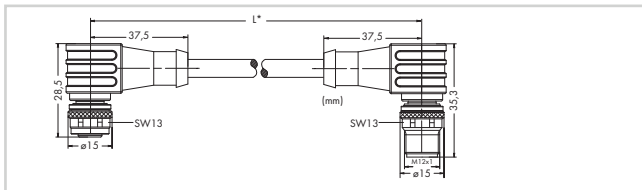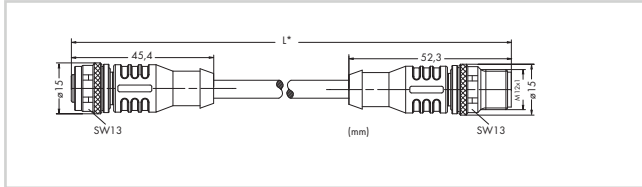

System bus cable for drag chain, M12 socket – M12 plug, straight, B coded		
	Item No.	Pack. Unit
M12 socket, straight, M12 plug, straight, 0.2 m	756-1505/060-002	1
M12 socket, straight, M12 plug, straight, 0.3 m	756-1505/060-003	1
M12 socket, straight, M12 plug, straight, 0.5 m	756-1505/060-005	1
M12 socket, straight, M12 plug, straight, 1 m	756-1505/060-010	1
M12 socket, straight, M12 plug, straight, 2 m	756-1505/060-020	1
M12 socket, straight, M12 plug, straight, 5 m	756-1505/060-050	1
M12 socket, straight, M12 plug, straight, 10 m	756-1505/060-100	1
M12 socket, straight, M12 plug, straight, 20 m	756-1505/060-200	1
M12 socket, straight, M12 plug, straight, 50 m	756-1505/060-500	1

System bus cable for drag chain, M12 socket – M12 plug, right angle, B coded		
	Item No.	Pack. Unit
M12 socket, right angle, M12 plug, right angle, 0.2 m	756-1506/060-002	1
M12 socket, right angle, M12 plug, right angle, 0.3 m	756-1506/060-003	1
M12 socket, right angle, M12 plug, right angle, 0.5 m	756-1506/060-005	1
M12 socket, right angle, M12 plug, right angle, 1 m	756-1506/060-010	1
M12 socket, right angle, M12 plug, right angle, 2 m	756-1506/060-020	1
M12 socket, right angle, M12 plug, right angle, 5 m	756-1506/060-050	1
M12 socket, right angle, M12 plug, right angle, 10 m	756-1506/060-100	1
M12 socket, right angle, M12 plug, right angle, 20 m	756-1506/060-200	1
M12 socket, right angle, M12 plug, right angle, 50 m	756-1506/060-500	1

System bus cable for drag chain		
	Item No.	Pack. Unit
25 m	756-1500/000-250	1
50 m	756-1500/000-500	1
100 m	756-1500/000-1000	1