




Power cable

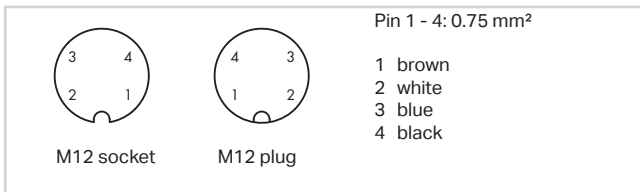


Connection technology	M12 socket/plug, A coded
Operating voltage	250 V AC/DC
Operating current	4 A
Rated surge voltage	2.5 kV
Suitable for drag chain applications	≥ 4 Mio. bending cycles
Ambient temperature (operation) moved	-30 ... +80 °C
Protection type	IP67
Cable diameter	6.2 mm ±0.2

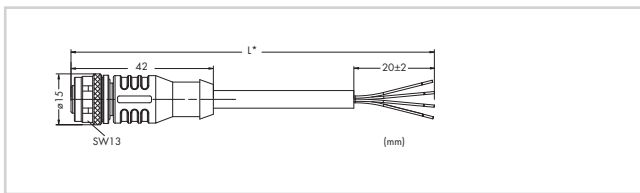


Power cable, M12 socket, straight, A coded		
	Item No.	Pack. Unit
M12 socket, straight, 2 m	756-3101/040-020	1
M12 socket, straight, 5 m	756-3101/040-050	1
M12 socket, straight, 10 m	756-3101/040-100	1
M12 socket, straight, 20 m	756-3101/040-200	1

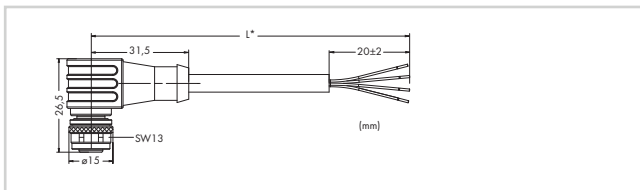

Power cable, M12 socket, right angle, A coded		
	Item No.	Pack. Unit
M12 socket, right angle, 2 m	756-3102/040-020	1
M12 socket, right angle, 5 m	756-3102/040-050	1
M12 socket, right angle, 10 m	756-3102/040-100	1
M12 socket, right angle, 20 m	756-3102/040-200	1


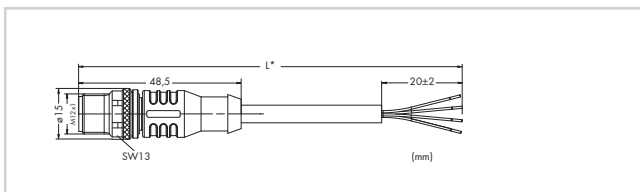


Power cable, M12 plug, straight, A coded		
	Item No.	Pack. Unit
M12 plug, straight, 2 m	756-3103/040-020	1
M12 plug, straight, 5 m	756-3103/040-050	1
M12 plug, straight, 10 m	756-3103/040-100	1
M12 plug, straight, 20 m	756-3103/040-200	1

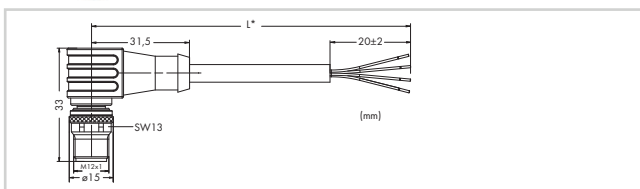

Power cable, M12 plug, right angle, A coded		
	Item No.	Pack. Unit
M12 plug, right angle, 2 m	756-3104/040-020	1
M12 plug, right angle, 5 m	756-3104/040-050	1
M12 plug, right angle, 10 m	756-3104/040-100	1
M12 plug, right angle, 20 m	756-3104/040-200	1

Power cable

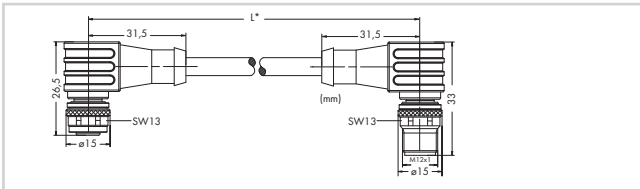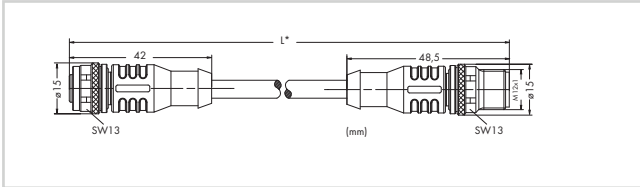

Power cable, M12 socket – M12 plug, straight, A coded		
	Item No.	Pack. Unit
M12 socket, straight, M12 plug, straight, 0.2 m	756-3105/040-002	1
M12 socket, straight, M12 plug, straight, 0.3 m	756-3105/040-003	1
M12 socket, straight, M12 plug, straight, 0.5 m	756-3105/040-005	1
M12 socket, straight, M12 plug, straight, 1 m	756-3105/040-010	1
M12 socket, straight, M12 plug, straight, 2 m	756-3105/040-020	1
M12 socket, straight, M12 plug, straight, 3 m	756-3105/040-030	1
M12 socket, straight, M12 plug, straight, 5 m	756-3105/040-050	1
M12 socket, straight, M12 plug, straight, 7 m	756-3105/040-070	1
M12 socket, straight, M12 plug, straight, 10 m	756-3105/040-100	1
M12 socket, straight, M12 plug, straight, 20 m	756-3105/040-200	1

Power cable, M12 socket – M12 plug, right angle, A coded		
	Item No.	Pack. Unit
M12 socket, right angle, M12 plug, right angle, 0.2 m	756-3106/040-002	1
M12 socket, right angle, M12 plug, right angle, 0.3 m	756-3106/040-003	1
M12 socket, right angle, M12 plug, right angle, 0.5 m	756-3106/040-005	1
M12 socket, right angle, M12 plug, right angle, 1 m	756-3106/040-010	1
M12 socket, right angle, M12 plug, right angle, 2 m	756-3106/040-020	1
M12 socket, right angle, M12 plug, right angle, 3 m	756-3106/040-030	1
M12 socket, right angle, M12 plug, right angle, 5 m	756-3106/040-050	1
M12 socket, right angle, M12 plug, right angle, 7 m	756-3106/040-070	1
M12 socket, right angle, M12 plug, right angle, 10 m	756-3106/040-100	1
M12 socket, right angle, M12 plug, right angle, 20 m	756-3106/040-200	1

Power cable		
	Item No.	Pack. Unit
25 m	756-3100/000-250	1
50 m	756-3100/000-500	1
100 m	756-3100/000-1000	1