
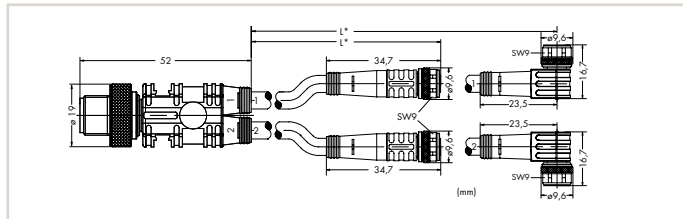


# Sensor/Actuator Cable; Fitted on Both Ends; Distribution Connector

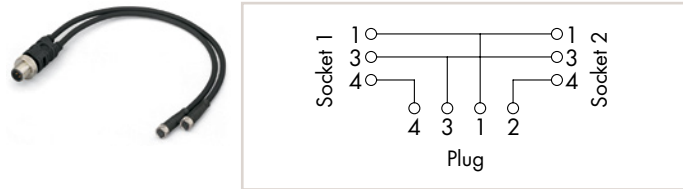




Operating voltage	60 VAC/DC
Operating current	4 A (max.)
Rated surge voltage	1.5 kV
Drag chain suitability	≥ 2 million bending cycles
Surrounding air temperature (operation), dynamic	-25 ... +90 °C
Protection type	IP67
Cable diameter	4.1 mm ±0.2

### Sensor/Actuator Cable; 2 x M8 socket (straight) – M12 plug (straight)

Pole No.	Cable Length	Item No.	Pack. Unit
4-pole	1 m	756-5513/040-010	10
4-pole	2 m	756-5513/040-020	10

### Sensor/Actuator Cable; 2 x M8 socket (angled) – M12 plug (straight)

Pole No.	Cable Length	Item No.	Pack. Unit
4-pole	1 m	756-5514/040-010	10
4-pole	2 m	756-5514/040-020	10

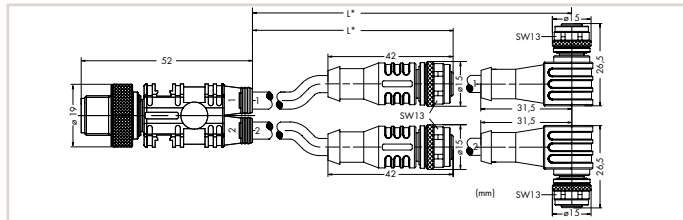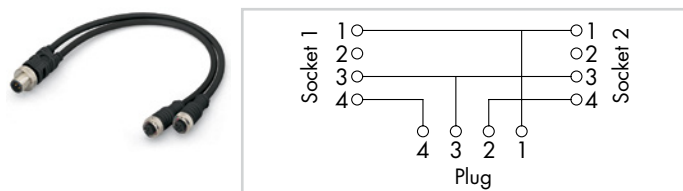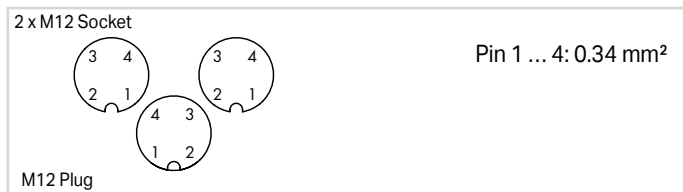


Operating voltage	250 VAC/DC
Operating current	4 A (max.)
Rated surge voltage	2.5 kV
Drag chain suitability	≥ 2 million bending cycles
Surrounding air temperature (operation), dynamic	-25 ... +90 °C
Protection type	IP67
Cable diameter	4.7 mm ±0.2

### Sensor/Actuator Cable; 2 x M12 socket (straight) – M12 plug (straight)

Pole No.	Cable Length	Item No.	Pack. Unit
4-pole	1 m	756-5516/040-010	10
4-pole	2 m	756-5516/040-020	10


### Sensor/Actuator Cable; 2 x M12 socket (angled) – M12 plug (straight)

Pole No.	Cable Length	Item No.	Pack. Unit
4-pole	1 m	756-5517/040-010	10
4-pole	2 m	756-5517/040-020	10

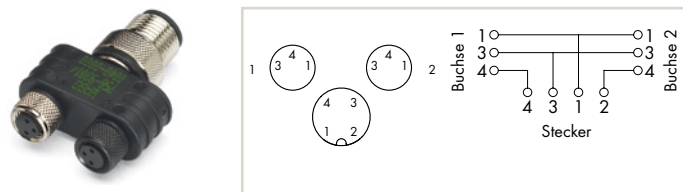

### Distribution Connector M8/M12

	Item No.	Pack. Unit
Accessories; M12/M8 Distribution Connector	756-9301/040-000	1

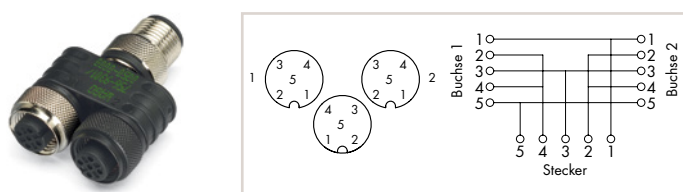

### Distribution Connector M12/M12

	Item No.	Pack. Unit
Accessories; M12/M12 Distribution Connector	756-9301/050-000	1