





Accessories

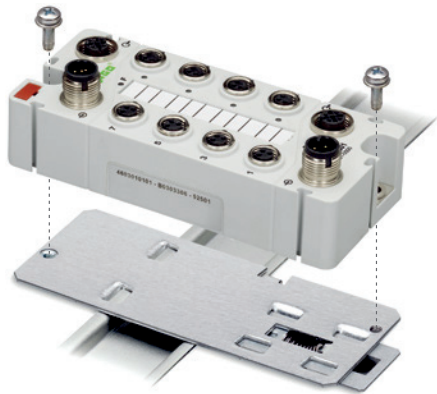

Carrier rail adapter		
	Item No.	Pack. Unit
Carrier rail adapter, for couplers/progr. couplers	767-121	1
Carrier rail adapter, for I/O and power distribution modules	767-122	1
Carrier rail adapter, for I/O module 8 x M12	767-125	1

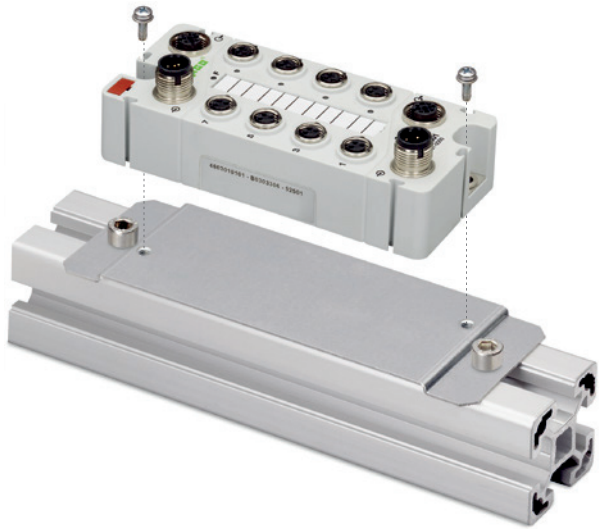


Profile adapter		
	Item No.	Pack. Unit
Profile adapter, for couplers/progr. couplers	767-123	1
Profile adapter, for I/O and power distribution modules	767-124	1
Profile adapter, for I/O module 8 x M12	767-126	1

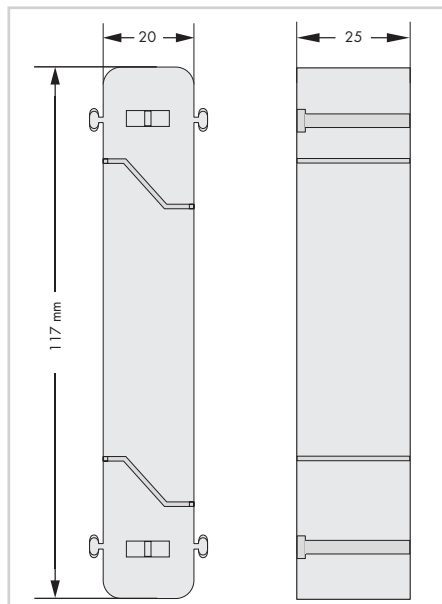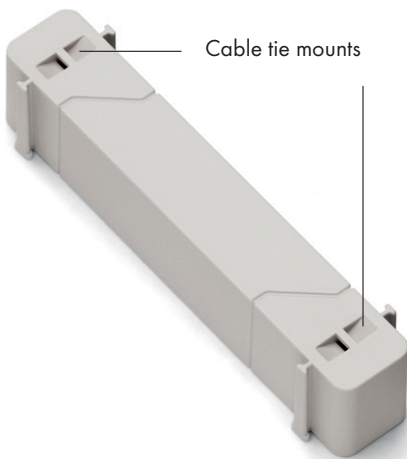

Spacer module		
	Item No.	Pack. Unit
	767-111	1

 Accessories



Marking strip		
	Item No.	Pack. Unit
Marking strip, 8xM8	767-101	100
Marking strip, 4xM12	767-102	100
Marking strip, for power distribution modules	767-103	100
Marking strip, 8 x M12	767-104	100
Marking strip, 9.9 mm wide, 50 m roll	757-901/000-050	1

Marking pen		
	Item No.	Pack. Unit
for permanent marking	210-110	1

Protective caps (for unused sockets)		
	Item No.	Pack. Unit
M8 protective cap	756-8101	10
M12 protective cap	756-8102	10

Protective caps (for unused plugs)		
	Item No.	Pack. Unit
M12 protective cap	756-8103	1

Protective caps (for unused plugs)		
	Item No.	Pack. Unit
M23 protective cap	756-8104	1

Locking clip (protects pre-assembled connectors from tool-free disconnection)		
	Item No.	Pack. Unit
Locking clip, M8	756-8301	10
Locking clip, M12	756-8302	10

Configurable shielded connectors



Conductor size
 Ø 6 ... 8 mm
 screw clamp connection:
 0.14 ... 0.75 mm²
 spring clamp connection:
 0.14 ... 0.5 mm²

M12 plug, straight		Item No.	Pack. Unit
Fitted pluggable connector, 5-pole shielded, M12 plug, straight A coded, Spring		756-9207/060-000	1
Fitted pluggable connector, 5-pole shielded, M12 plug, straight B coded, Spring		756-9401/060-000	1
Fitted pluggable connector, 5-pole shielded, M12 plug, straight B coded, Screw		756-9411/060-000	1
Fitted pluggable connector, 4-pole shielded, M12 plug, straight D coded, Spring		756-9501/060-000	1



Conductor size
 Ø 6 ... 8 mm
 screw clamp connection:
 0.14 ... 0.75 mm²
 spring clamp connection:
 0.14 ... 0.5 mm²

M12 plug, right angle		Item No.	Pack. Unit
Fitted pluggable connector, 5-pole shielded, M12 plug, right angle A coded, Spring		756-9211/060-000	1
Fitted pluggable connector, 5-pole shielded, M12 plug, right angle B coded, Spring		756-9403/060-000	1
Fitted pluggable connector, 5-pole shielded, M12 plug, right angle B coded, Screw		756-9413/060-000	1
Fitted pluggable connector, 4-pole shielded, M12 plug, right angle D coded, Spring		756-9501/040-000	1



Conductor size
 Ø 6 ... 8 mm
 screw clamp connection:
 0.14 ... 0.75 mm²
 spring clamp connection:
 0.14 ... 0.5 mm²

M12 socket, straight		Item No.	Pack. Unit
Fitted pluggable connector, 5-pole shielded, M12 socket, straight A coded, Spring		756-9208/060-000	1
Fitted pluggable connector, 5-pole shielded, M12 socket, straight B coded, Spring		756-9402/060-000	1
Fitted pluggable connector, 5-pole shielded, M12 socket, straight B coded, Screw		756-9412/060-000	1



Conductor size
 Ø 6 ... 8 mm
 screw clamp connection:
 0.14 ... 0.75 mm²
 spring clamp connection:
 0.14 ... 0.5 mm²

M12 socket, right angle		Item No.	Pack. Unit
Fitted pluggable connector, 5-pole shielded, M12 socket, right angle A coded, Spring		756-9210/060-000	1
Fitted pluggable connector, 5-pole shielded, M12 socket, right angle B coded, Spring		756-9404/060-000	1
Fitted pluggable connector, 5-pole shielded, M12 socket, right angle B coded, Screw		756-9414/060-000	1





Conductor size
 Ø 6 ... 8 mm/
 0.14 ... 0.50 mm²

8-pole

M12 socket, straight and right angle		Item No.	Pack. Unit
Fitted pluggable connector, 8-pole shielded, M12 socket, straight, Screw		756-9211/090-000	1
Fitted pluggable connector, 8-pole shielded, M12 socket, right angle, Screw		756-9214/090-000	1

 
 
Configurable connectors with PG9 thread



Conductor size
 \varnothing 6 ... 8 mm
 screw clamp connection:
 0.25 ... 0.75 mm²
 spring clamp connection:
 0.14 ... 0.5 mm²

M12 plug, straight



	Item No.	Pack. Unit
Fitted pluggable connector, 4-pole, M12 plug, straight A coded, Screw	756-9203/040-000	1
Fitted pluggable connector, 5-pole, M12 plug, straight A coded, Spring	756-9203/050-000	1

 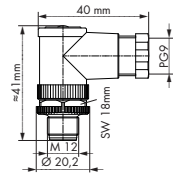

Conductor size
 \varnothing 6 ... 8 mm
 screw clamp connection:
 0.25 ... 0.75 mm²
 spring clamp connection:
 0.14 ... 0.5 mm²

M12 plug, right angle



	Item No.	Pack. Unit
Fitted pluggable connector, 4-pole, M12 plug, right angle A coded, Screw	756-9206/040-000	1
Fitted pluggable connector, 5-pole, M12 plug, right angle A coded, Spring	756-9206/050-000	1

  

Conductor size
 \varnothing 6 ... 8 mm
 screw clamp connection:
 0.25 ... 0.75 mm²
 spring clamp connection:
 0.14 ... 0.5 mm²

M12 socket, straight

	Item No.	Pack. Unit
Fitted pluggable connector, 4-pole, M12 socket, straight A coded, Screw	756-9213/040-000	1
Fitted pluggable connector, 5-pole, M12 socket, straight A coded, Spring	756-9213/050-000	1

 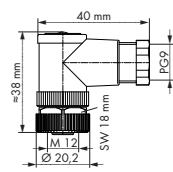


Conductor size
 \varnothing 6 ... 8 mm
 screw clamp connection:
 0.25 ... 0.75 mm²
 spring clamp connection:
 0.14 ... 0.5 mm²

M12 socket, right angle

	Item No.	Pack. Unit
Fitted pluggable connector, 4-pole, M12 socket, right angle A coded, Screw	756-9216/040-000	1
Fitted pluggable connector, 5-pole, M12 socket, right angle A coded, Spring	756-9216/050-000	1

USB communication cable, terminating resistors, T-piece

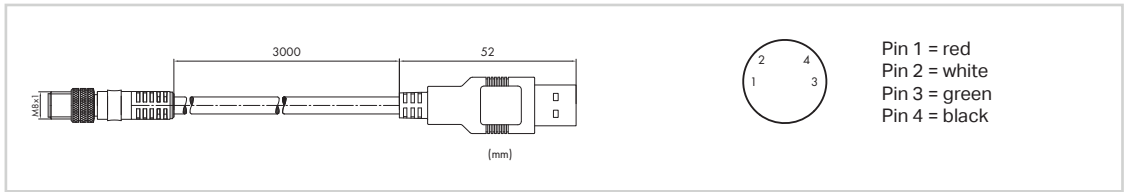


USB communication cable

	Item No.	Pack. Unit
USB communication cable, M8 plug, straight, USB Typ A plug, straight, 3 m	756-4101/042-030	1




System bus terminating plug

	Item No.	Pack. Unit
M12 system bus terminating plug, B coded, straight	756-9409/060-000	1

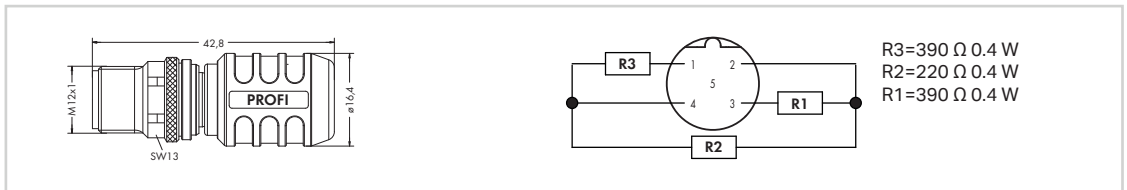


PROFIBUS terminating plug

	Item No.	Pack. Unit
M12 PROFIBUS terminating plug, B coded, straight	756-9405/060-000	1

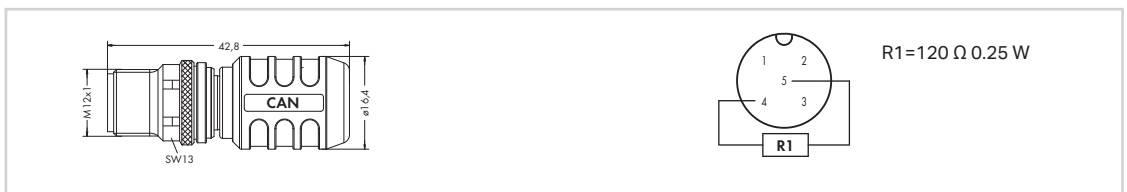

CANopen, DeviceNet terminating plug


	Item No.	Pack. Unit
M12 CANopen, DeviceNet terminating plug, A coded, straight	756-9209/060-000	1

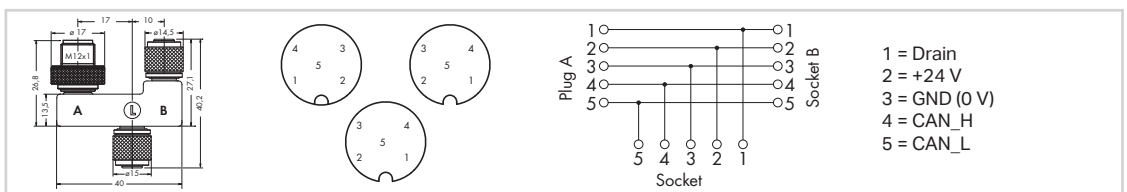

DeviceNet drop T-piece

	Item No.	Pack. Unit
M12 DeviceNet drop T-piece	756-9303/050-000	1


ETHERNET, PROFINET accessories

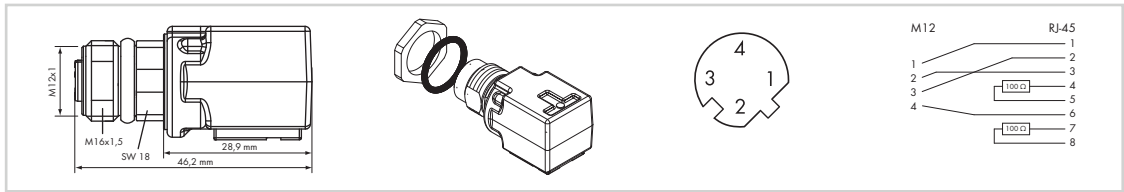

Adapter, right angle, M12 socket, D coded/RJ-45 socket

Adapter, right angle, M12 socket, D coded/RJ-45 socket (also ideally suited for control cabinet feedthrough applications or connecting IP67/IP20 components)


Item No.	Pack. Unit
756-9503/040-000	1

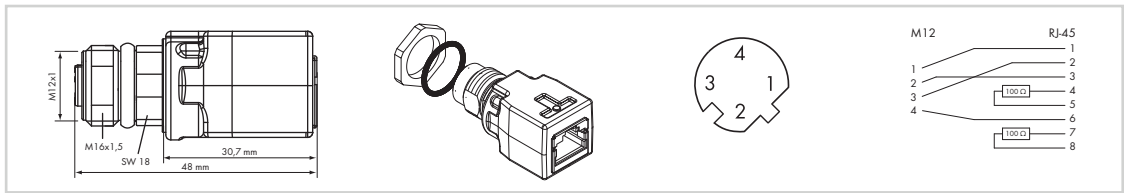

Adapter, straight, M12 socket, D coded/RJ-45 socket

Adapter, straight, M12 socket, D coded/RJ-45 socket (also ideally suited for control cabinet feed-through applications) or connecting IP67/IP20 components)


Item No.	Pack. Unit
756-9504/040-000	1

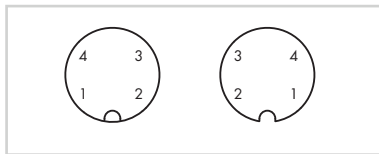

M12 socket / M12 plug, A coded

M12 panel feed-through connectors, A coded

Item No.	Pack. Unit
756-9217/050-000	1

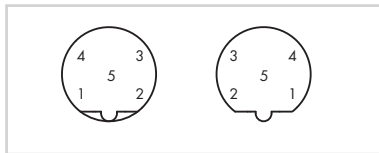


M12 socket / M12 plug, B coded

M12 panel feed-through connectors, B coded

Item No.	Pack. Unit
756-9406/050-000	1


M12 termination and M23 configurable connectors

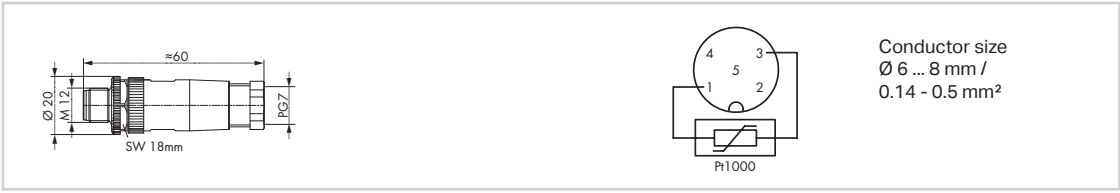

Conductor size
 Ø 6 ... 8 mm /
 0.14 - 0.5 mm²


Compensation connector, M12 plug, for 767-6403 Thermocoupler Module (Pt1000 sensor integrated)

	Item No.	Pack. Unit
Compensation connector, M12 plug, straight, 5 poles, spring clamp technology	756-9207/050-000	1

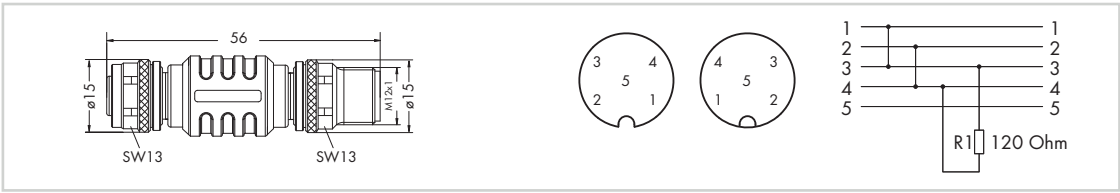

Termination M12


	Item No.	Pack. Unit
RS-422/-485 Termination M12	756-9218/050-000	1

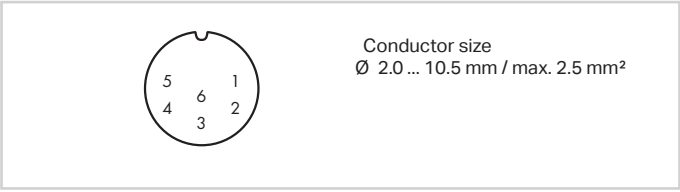

Conductor size
 Ø 2.0 ... 10.5 mm / max. 2.5 mm²

M23 plug

	Item No.	Pack. Unit
Fitted pluggable connector, 6-pole, M23 plug, straight, Solder	756-9601/060-000	1
Fitted pluggable connector, 6-pole, M23 plug, right angle, Solder	756-9602/060-000	1

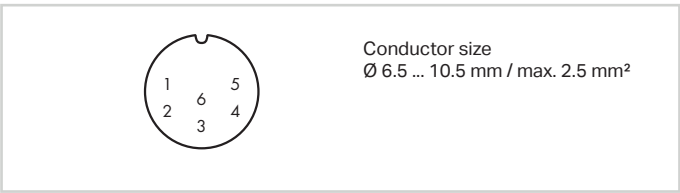

Conductor size
 Ø 6.5 ... 10.5 mm / max. 2.5 mm²

M23 socket

	Item No.	Pack. Unit
Fitted pluggable connector, 6-pole, M23 socket, straight, Solder	756-9603/060-000	1
Fitted pluggable connector, 6-pole, M23 socket, right angle, Solder	756-9604/060-000	1



M23 assembly key

	Item No.	Pack. Unit
M23 assembly key	756-8201	1