


**Magnetic-Mount Antenna; with 2.5 m Cable and SMA Angled Plug;
GSM/UMTS/LTE/Bluetooth®/WLAN; 698-960, 1400-1518, 1710-2700 MHz**

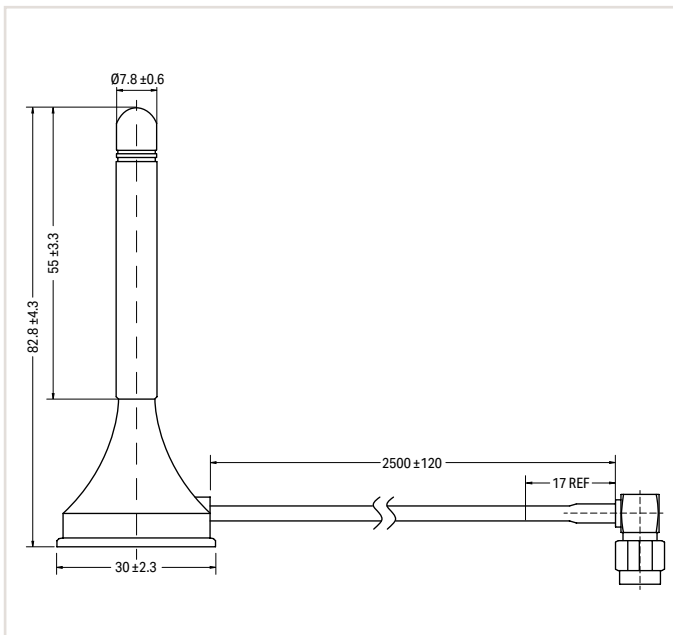

Item Description

Item No.

Technical Data

Radio technology
Frequency band

Gain

Mechanical Data

Connector
Connection cable length
Mounting type
Cable type
Weight
Surrounding air temperature (operation)

**Magnetic-Mount Antenna; with 2.5 m Cable and SMA Angled Plug; GSM/
UMTS/LTE/Bluetooth®/WLAN; 698-960, 1400-1518, 1710-2700 MHz
758-975**

GSM; UMTS; LTE; Bluetooth®; WLAN

B1 ... B23; B25 ... B30; B32 ... B42; B48; B66; B74 ... 76; B78
Frequency range: 698 ... 960 MHz; 1400 ... 1518 MHz; 1710 ... 2700 MHz

3 dBi

SMA angled plug

2.5 m

Magnetic stand

RG-174

44 g

-40 ... +85 °C